

Technical data sheet

Underfloor box with GES9

Item number: 7427475



Square screed socket with GES9 UGE service outlet for use in screed floors for indoor use. With pre-marked insertion openings for pipelines (M20/M25) on all four sides.

In the as-delivered state, the installation housing is closed with a mounting protection lid.

The minimum installation depth is 65 mm, the height-adjustment range +25 mm.

Three type APMT5 cover plates can be installed.



PA Polyamide

Master data

Item number	7427475
Type	GES9 BOX 7011 BS
Description 1	Service outlet-Set
Description 2	for BS sockets
Manufacturer	OBO
Dimension	264x264x91
Colour	Iron grey; RAL 7011
Material	Polyamide
Smallest sales unit	1
Unit of quantity	Piece
Weight	290 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	11,6274 kg CO2e / 1 Piece


Technical data sheet

Underfloor box with GES9


Item number: 7427475



Dimensions

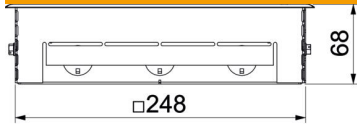

Length	264 mm
Width	264 mm

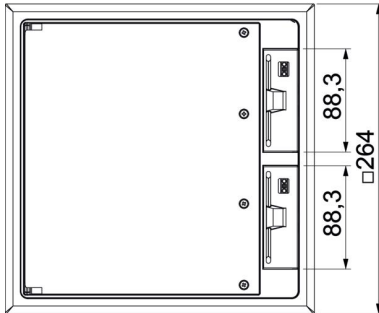

Technical data

Number of installable devices	6
Cable outlet version	Swivellable cord outlet
Floor care	Dry
Seal installation option	no
Screed height, max.	85 mm
Screed height, min.	65 mm
Suitable for raised floor installation	no
Suitable for screed-flush closed underfloor ducts	no
Suitable for screed-covered underfloor ducts	no
Suitable for cavity floor installation	no
Suitable for underfloor ducts	no
Nominal size for device installation units	9
Height-adjustment range, max.	85 mm
Height-adjustment range, min.	65 mm
Frame version	Carpet protection frame
Protection rating (IP) when used	IP20
Protection rating (IP) when unused	IP40
Protection rating IK code	IK08
Heavy-duty version	no
Vertical load, large area	to 3,000 N
Vertical load, small area	to 2,000 N
Opening mechanism	Handle
Floor covering thickness	10 mm