

Technical data sheet

External corner, for device installation trunking Rapid 80 type GK-70110

Item number: 6274311



External corner for changing the direction of the GK device installation trunking.
Cover must be ordered separately.



PVC Polyvinylchloride

Master data

Item number	6274311
Type	GK-A70110CW
Description 1	External corner
Manufacturer	OBO
Dimension	70x110mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	116 kg
Weight unit	kg/100 pc.


Technical data sheet

External corner, for device installation trunking Rapid 80 type GK-70110

Item number: 6274311



Dimensions

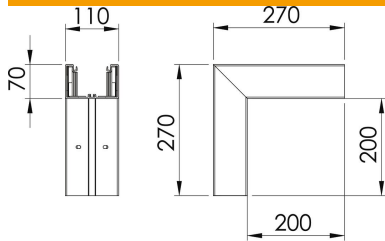

Length	270 mm
Width	110 mm
Height	70 mm

Technical data

Number of covers	1
Version for	Base
Halogen-free	no
Cable retaining clip	no
Duct connector	no
Cover mounting type	Internal
Mounting perforation in base	yes
Cover width	76.5 mm
Cover width 2	0 mm
Cover width 3	0 mm
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C
Angle range, max.	90 mm
Angle range, min.	90 mm