

Technical data sheet

End piece, for device installation trunking Rapid 80 type
70110

Item number: 6274374



End piece for closing the device installation trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data		
Item number	6274374	
Type	GK-E70110WA	
Description 1	End piece	
Manufacturer	OBO	
Dimension	70x110mm	
Colour	White aluminium; RAL 9006	
Material	Polycarbonate/Acrylnitrile-butadiene-styrene	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	4.9 kg	
Weight unit	kg/100 pc.	


Technical data sheet

End piece, for device installation trunking Rapid 80 type
70110

Item number: 6274374



Dimensions

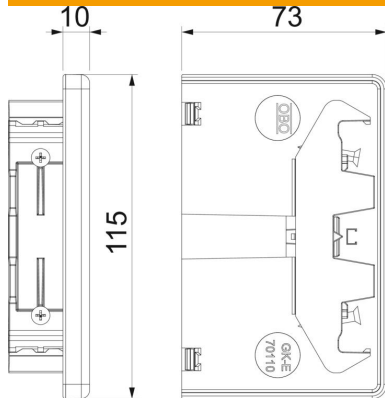

Length	29 mm
Width	115 mm
Height	73 mm

Technical data

Version for	Symmetrical
Fastening type	Screw-on
for duct width	110 mm
for trunking height	70 mm
Suitable for	Left/right
Halogen-free	no
Cut lamination	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C