

Technical data sheet

End piece, for device installation trunking Rapid 80 type
70130

Item number: 6274576



End piece for closing the device installation trunking.



PVC Polyvinylchloride

Master data

Item number	6274576
Type	GK-E70130GR
Description 1	End piece
Manufacturer	OBO
Dimension	70x130mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	5.621 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2155 kg CO2e / 1 Piece


Technical data sheet

End piece, for device installation trunking Rapid 80 type
70130

Item number: 6274576



Dimensions

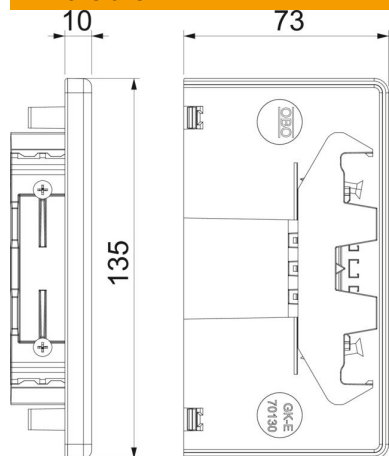

Length	29 mm
Width	135 mm
Height	73 mm

Technical data

Version for	Symmetrical
Fastening type	Screw-on
for duct width	130 mm
for trunking height	70 mm
Suitable for	Left/right
Halogen-free	no
Cut lamination	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C