

# Technical data sheet

End piece, for device installation trunking Rapid 80 type  
70170

Item number: 6274774



End piece for closing the device installation trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

## Master data

Item number	6274774
Type	GK-E70170WA
Description 1	End piece
Manufacturer	OBO
Dimension	70x170mm
Colour	White aluminium; RAL 9006
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	4.9 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2837 kg CO2e / 1 Piece


# Technical data sheet

End piece, for device installation trunking Rapid 80 type  
70170

Item number: 6274774



## Dimensions

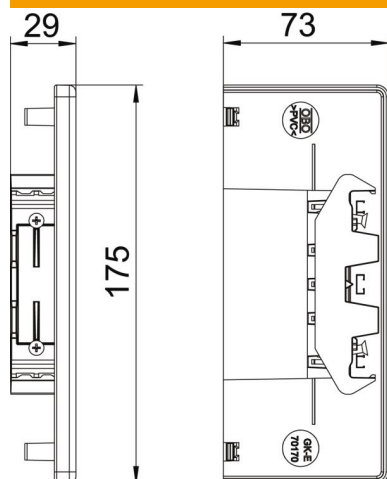

Length	29 mm
Width	175 mm
Height	73 mm

## Technical data

Version for	Symmetrical
Fastening type	Screw-on
for duct width	170 mm
for trunking height	70 mm
Suitable for	Left/right
Halogen-free	no
Cut lamination	yes
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C