

Technical data sheet

Flat angle hood, for device installation trunking Rapid 45-2
type GK-53130

Item number: 6113272



Flat angle as hood fitting for changing the direction of the Rapid 45-2 device installation trunking.



Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6113272
Type	GK-FH53130LGR
Description 1	Flat angle
Description 2	hood fitting
Manufacturer	OBO
Dimension	172x172x56
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	14.754 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,8504 kg CO2e / 1 Piece


Technical data sheet

Flat angle hood, for device installation trunking Rapid 45-2
type GK-53130

Item number: 6113272



Dimensions

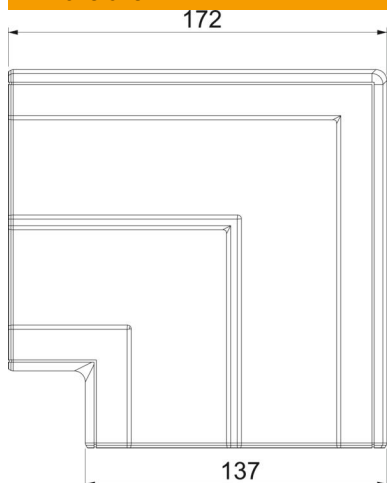

Length	172 mm
Width	137 mm
Height	55.5 mm

Technical data

Number of covers	1
Version for	Hood fitting
for duct width	130 mm
for trunking height	53 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Cover width	0 mm
Cover width 2	0 mm
Cover width 3	0 mm
Change of direction	Vertical, rising/falling
Protection rating	IP40
Protective film	no
Protection rating IK code	IK08
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C
Angle range, max.	90 mm
Angle range, min.	90 mm