

# Technical data sheet

Flat angle hood, for device installation trunking Rapid 80  
type 70210  
Item number: 6273920



Flat angle hood fitting made of halogen-free PC/ABS for simple creation of a rising or falling 90° change of direction with device installation trunking of the Rapid 80 GK, GKH, GS and GA series. The flat angle cover fitting can be used for symmetrical and asymmetrical trunking types.



**PC/ABS** Polycarbonate/Acrylnitrile-butadiene-styrene

## Master data


Item number	6273920
Type	GK-FH70210RW
Description 1	Flat angle
Description 2	hood fitting
Manufacturer	OBO
Dimension	70x210mm
Colour	Pure white; RAL 9010
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	26.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,6242 kg CO2e / 1 Piece

# Technical data sheet

Flat angle hood, for device installation trunking Rapid 80  
type 70210  
Item number: 6273920



## Dimensions

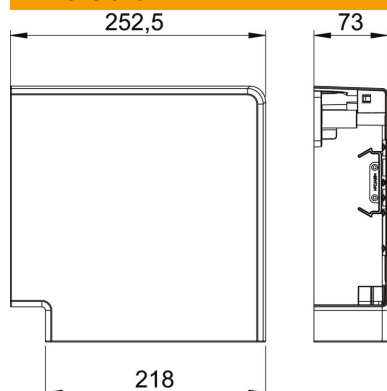

Length	252.5 mm
Width	218 mm
Height	73 mm

## Technical data

Number of covers	1
Version for	Hood fitting
for duct width	210 mm
for trunking height	70 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Cover width	0 mm
Cover width 2	0 mm
Cover width 3	0 mm
Change of direction	Vertical, rising/falling
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Symmetrical	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C
Angle range, max.	90 mm
Angle range, min.	90 mm