

Technical data sheet

Trunking connector and joint cover

Item number: 6113024



Joint cover for the bases of the Rapid 45-2 device installation trunking to hide cut edges and provide a perfect connection of the trunking segments. The joint covers are attached. Suitable for trunking width 100 mm and 165 mm.



PC/ABS

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data	
Item number	6113024
Description 1	Joint cover
Description 2	for Rapid 45-2 100 and 165
Manufacturer	OBO
Dimension	168x55x15
Colour	aluminium
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	0.58 kg
Weight unit	kg/100 pc.


Technical data sheet

Trunking connector and joint cover

Item number: 6113024



Dimensions

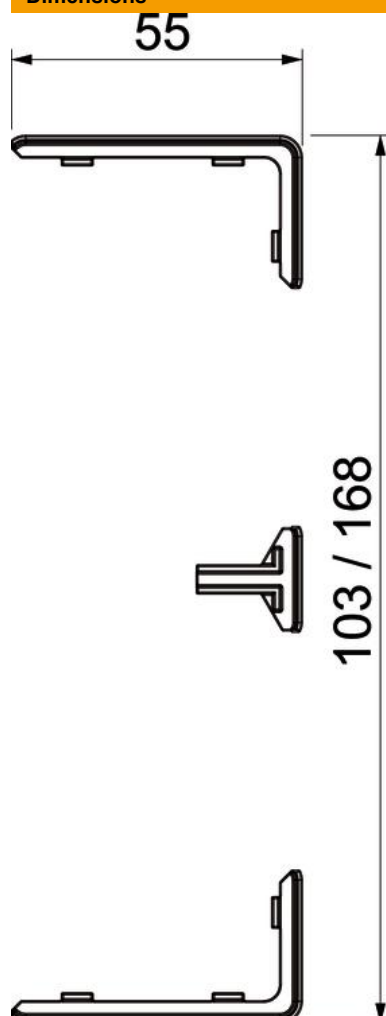

Length	15 mm
Width	55 mm
Height	27 mm

Technical data sheet

Trunking connector and joint cover

Item number: 6113024



Technical data

Version for	Trunking cut cover
Fastening type	Slide (before mounting)
Shape	Symmetrical
for duct width	100.17 mm
for trunking height	53 mm
Halogen-free	yes
Cover width	45 mm
Protection rating	IP40
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C