


Technical data sheet

External corner cover, smooth

Item number: 6274796



PVC external corner cover, smooth surface.

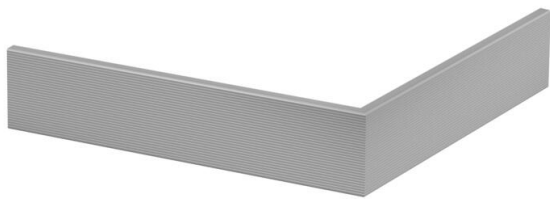

Master data		
Item number	6274796	
Type	GK-OTGAGR	
Description 1	Cover	
Description 2	external corner, smooth	
Manufacturer	OBO	
Colour	Stone grey; RAL 7030	
Material	Polyvinylchloride	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	9.5 kg	
Weight unit	kg/100 pc.	


Technical data sheet

External corner cover, smooth

Item number: 6274796



Dimensions

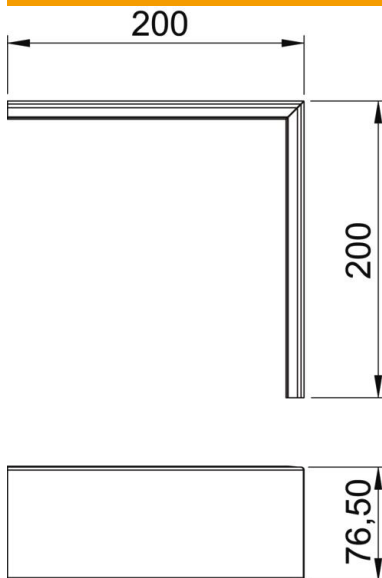

Length	200 mm
Width	76.5 mm
Height	12 mm

Technical data

Application	External corner
Halogen-free	no
Cover mounting type	Internal
Protection rating	IP30
Protective film	yes
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C