

Technical data sheet

Plastic trunking cover, smooth

Item number: 6278686



Smooth trunking cover, for closing device installation trunking with 76.5 mm system opening.



PVC Polyvinylchloride

Master data

Item number	6278686
Type	GK-OTGGR
Description 1	Cover
Description 2	smooth
Manufacturer	OBO
Dimension	80x2000mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	27.5 kg
Weight unit	kg/100 m


Technical data sheet

Plastic trunking cover, smooth

Item number: 6278686



Dimensions

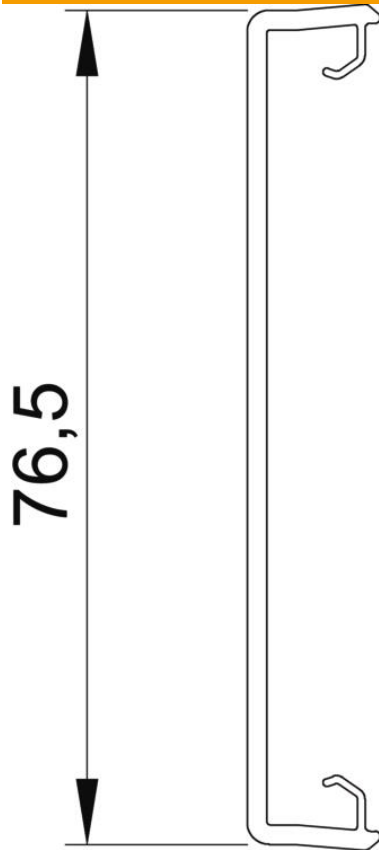

Length	2,000 mm
Width	76.5 mm
Height	12 mm

Technical data

Version for	Smooth
Cover mounting type	Internal
Protection rating	IP30
Protection rating IK code	IK08
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C