

# Technical data sheet

T piece adapter, for device installation trunking Rapid 45-2  
type 53130

Item number: 6113302



T piece adapter to create a 90° junction of the system size 53130 on the system size 53130.



Polycarbonate/Acrylnitrile-butadiene-styrene

## Master data

Item number	6113302
Type	GK-TR53130LGR
Description 1	T piece adaptor
Description 2	for Rapid 45-2, 2-compartment
Manufacturer	OBO
Dimension	190x52x56
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	3.514 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2742 kg CO2e / 1 Piece


# Technical data sheet

T piece adapter, for device installation trunking Rapid 45-2  
type 53130

Item number: 6113302



## Dimensions

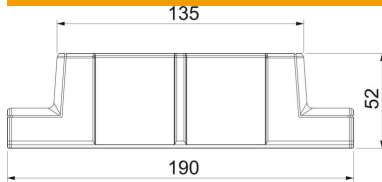

Length	190 mm
Width	52 mm
Height	55.5 mm

## Technical data

Number of covers	0
Version for	Hood fitting
for duct width	130 mm
for trunking height	53 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Cover width	0 mm
Cover width 2	0 mm
Cover width 3	0 mm
Protection rating	IP40
Protective film	no
Protection rating IK code	IK08
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C