


Technical data sheet

T piece adapter, for device installation trunking Rapid 45-2
type 53165

Item number: 6113482



T piece adapter to create a 90° junction of the system size 53165 on the system size 53165.

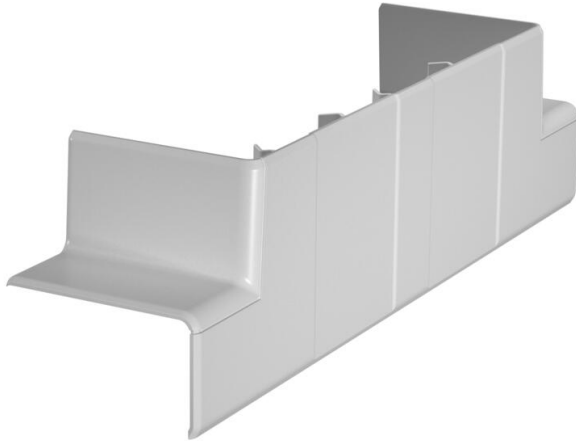

Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6113482
Type	GK-TR53165LGR
Description 1	T piece adaptor
Description 2	for Rapid 45-2 165
Manufacturer	OBO
Dimension	225x62x56
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	1
Unit of quantity	Piece
Weight	4.515 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece adapter, for device installation trunking Rapid 45-2
type 53165

Item number: 6113482



Dimensions

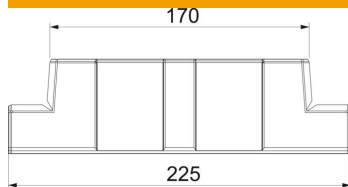

Length	225 mm
Width	62 mm
Height	55.5 mm

Technical data

Number of covers	0
Version for	Hood fitting
for duct width	165 mm
for trunking height	53 mm
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Cover mounting type	Cross-over
Mounting perforation in base	no
Cover width	0 mm
Cover width 2	0 mm
Cover width 3	0 mm
Protection rating	IP40
Protective film	no
Protection rating IK code	IK08
Symmetrical	no
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-15 °C