


# Technical data sheet

## Hexagonal bolt DIN 933 V2A

Item number: 3156044



Hexagonal bolt according to DIN 933 with metric thread.

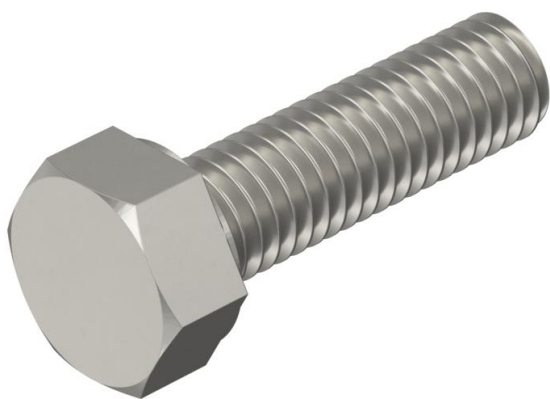

|    |                 |
|----|-----------------|
| A2 | Stainless steel |
| 2B | Bright, treated |

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 3156044                 |
| Type                              | HHS M16x50 A2           |
| Description 1                     | Hexagonal screw         |
| Description 2                     | fully threaded          |
| Manufacturer                      | OBO                     |
| Dimension                         | M16x50mm                |
| Material                          | Stainless steel         |
| Surface                           | Bright, treated         |
| Surface standard                  |                         |
| Smallest sales unit               | 50                      |
| Unit of quantity                  | Piece                   |
| Weight                            | 10.3 kg                 |
| Weight unit                       | kg/100 pc.              |
| CO Footprint (GWP) Cradle-to-Gate | 0,4908 kg COe / 1 Piece |


# Technical data sheet

## Hexagonal bolt DIN 933 V2A

Item number: 3156044



### Dimensions

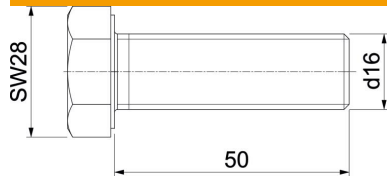

|             |       |
|-------------|-------|
| Length      | 50 mm |
| Dimension D | 16 mm |
| Dimension d | 16 mm |
| Dimension L | 50 mm |

### Technical data

|               |     |
|---------------|-----|
| Thread        | M16 |
| Thread metric | 16  |
| WAF           | 24  |