

Technical data sheet

Hexagonal nut DIN 934 V4A

Item number: 3400177



Hexagonal nut to DIN 934 with metric thread.



- A4 Stainless steel
- 2B Bright, treated

Master data	
Item number	3400177
Type	HN M10 A4
Description 1	Hexagonal nut
Manufacturer	OBO
Dimension	M10
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.084 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0559 kg COe / 1 Piece


Technical data sheet

Hexagonal nut DIN 934 V4A

Item number: 3400177



Dimensions

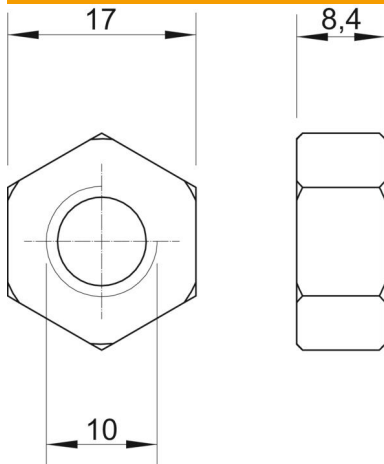

Dimension d	10 mm
Dimension h	8.4 mm

Technical data

Thread	M10
Thread metric	10
Thread type	Metric
Halogen-free	yes
With flange	no
WAF	17
Self-locking	no
Left thread	no
Thread, imperial	3/8"
Nut version	Nut
Screw system nut	Hexagon head