

Technical data sheet

Adapter plate for cable support system

Item number: 6290456



Adapter plate for mounting of a bracket for a cable support system to the ISS industrial service pole. Mounting instructions are included. Please observe the maximum load values. The bracket was tested with the adapter plate on the pole profile. The installation engineer must choose the ideal fastening system to match the substrate.



St Steel

Master data

Item number	6290456
Type	ISS160160APKTSWA
Description 1	Adapter plate
Description 2	for bracket mounting
Manufacturer	OBO
Dimension	166x216x56
Colour	White aluminium; RAL 9006
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	142 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,2723 kg CO2e / 1 Piece


Technical data sheet

Adapter plate for cable support system


Item number: 6290456



Dimensions

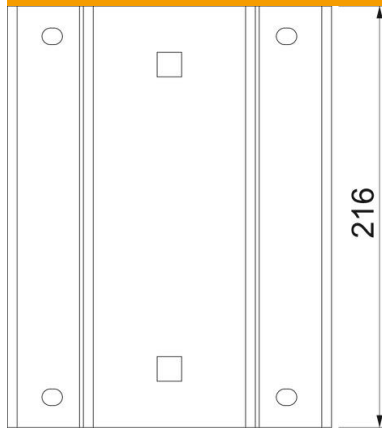

Length	216 mm
Width	166 mm
Width	166 in
Height	56 mm

 

Technical data

Version for	Vertical
Fastening type	Screw fastening
Rustproof steel, pickled	no
Protection rating	IP30
Protection rating IK code	IK10
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-25 °C