

# Technical data sheet

Service pole, type ISSHS140500

Item number: 6290033

 


ISS aluminium service pole, 2-compartment, with a 76.5 mm system opening.

Empty, equippable with standard devices (socket, telephone, etc.) max. 8 devices.

Fixing possible directly on floor. Accessory mounting boxes to be ordered separately.

The service pole is suitable for accepting front-locking accessory mounting boxes of the series 71GD.... The installation of a partition of type GA-TW (6279711) and the installation of the cover clip, type KL80A, are possible as an option.



**Alu** Aluminium

**EL** Anodised

## Master data

Item number	6290033
Type	ISSHS140500EL
Description 1	Service pole
Description 2	floor
Manufacturer	OBO
Dimension	500x130x140
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	354.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	38,6183 kg CO2e / 1 Piece


# Technical data sheet

Service pole, type ISSHS140500


Item number: 6290033



## Dimensions

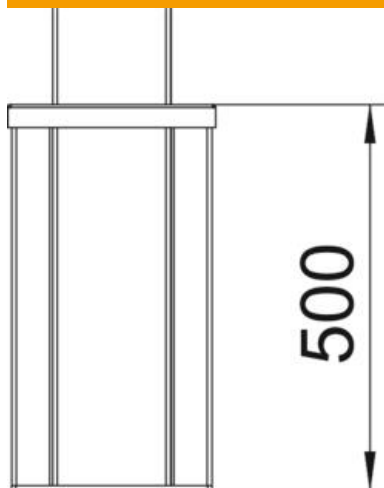

Length	500 mm
Width	130 mm
Height	140 mm

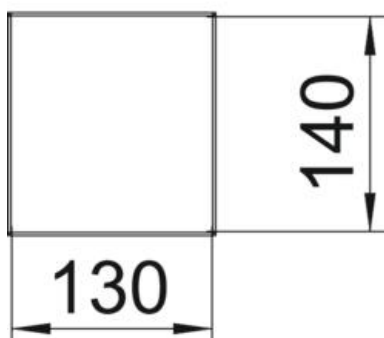

# Technical data sheet

Service pole, type ISSHS140500

Item number: 6290033



## Technical data

Number of usable covers	2
Number of compartments	2 St.
Version for	Double-sided
Fastening type	Bolts
Floor mounting	yes
Ceiling mounting	no
Continuous profile	yes
Halogen-free	yes
Cable entry	Bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Rectangular
Pole height, min.	500 mm
Adjustable	no
Pre-wired	no