

Technical data sheet

 
Service pole, type ISSHS4

Item number: 6286700



ISS sheet steel service pole with a 76.5 mm system opening on four sides.

Empty, fittable from all four sides with six standard devices (socket, telephone, etc.) on each side, max. 24 devices. Fastening possible directly on the floor. Accessory mounting boxes to be ordered separately. The service pole is suitable for accepting front locking accessory mounting boxes of the series 71GD....



St Steel

Master data

Item number	6286700
Type	ISSHS4RW
Description 1	Service pole
Description 2	floor
Manufacturer	OBO
Dimension	680x212x212
Colour	Pure white; RAL 9010
Material	Steel
Smallest sales unit	1
Unit of quantity	Piece
Weight	1050 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	36,2655 kg CO2e / 1 Piece


Technical data sheet

Service pole, type ISSHS4

Item number: 6286700



Dimensions

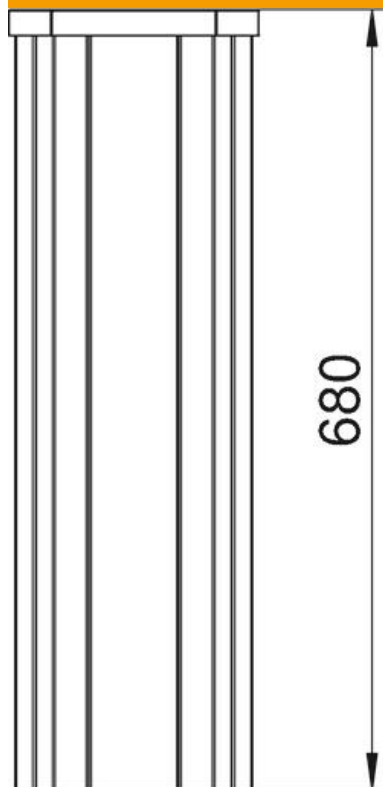

Length	680 mm
Width	212 mm
Height	212 mm



Technical data sheet

Service pole, type ISSHS4

Item number: 6286700



Technical data

Number of usable covers	4
Number of compartments	4 St.
Version for	Miscellaneous
Fastening type	Bolts
Floor mounting	yes
Ceiling mounting	no
Continuous profile	yes
Halogen-free	yes
Cable entry	Bottom
Cover width	76.5 mm
Changes according to location	no
Pole shape	Square
Pole height, min.	680 mm
Adjustable	no
Pre-wired	no