

# Technical data sheet

Plastic pipe, rigid, halogen-free

Item number: 2047722



Electrical installation pipe to EN 61386-1, made of halogen-free plastic to EN 50642, for the mechanical protection of cables.



Polycarbonate/Acrylnitrile-butadiene-styrene

## Master data

Item number	2047722
Type	KH25 LGR
Description 1	Plastic armoured pipe
Description 2	halogen-free
Manufacturer	OBO
Dimension	Ø25, 3000mm
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	57
Unit of quantity	Metre
Weight	14.8 kg
Weight unit	kg/100 m


# Technical data sheet

Plastic pipe, rigid, halogen-free

Item number: 2047722



## Dimensions

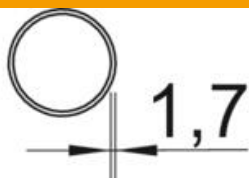

Length	3,000 mm
Dimension D	25 mm
Dimension L	3,000 mm
Dimension m (mm)	M25
Dimension t	1.7 mm

M25



3000



# Technical data sheet

Plastic pipe, rigid, halogen-free

Item number: 2047722



## Technical data

Bending behaviour	rigid
Pressure resistance	Heavy (1,250 N)
Use temperature, max.	+ 90 °C
Use temperature, min.	- 15 °C
Size	M25
Halogen-free	yes
Classification code	0
Impact resistance	Heavy (2.0 kg/300 mm)