

Technical data sheet

Head plate, transverse

Item number: 6347061



Head plate for installation in IS 8 support. The cable trays and ladders run in a transverse direction.
Including appropriate fastening material.

Limit the length of the support to max. 2,000 mm.



St Steel

FT Hot-dip galvanised

Master data

Item number	6347061
Description 1	Head plate
Description 2	for IS 8 support, turned 90°
Manufacturer	OBO
Dimension	200mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	158.4 kg
Weight unit	kg/100 pc.


Technical data sheet

Head plate, transverse

Item number: 6347061



Dimensions

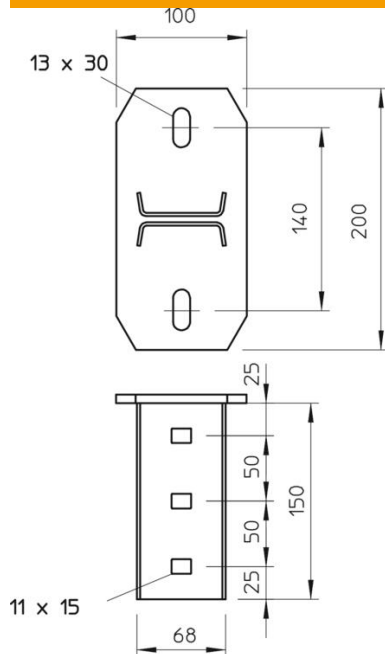

Length	200 mm
Width	100 mm
Height	156.5 mm

Technical data

Version for	Screw head plate
Suitable for ceiling fastening	yes
Suitable for panel fastening	no
Suitable for profile shapes	I profile
Rustproof steel, pickled	no
Angle range, max.	90 mm
Angle range, min.	90 mm