


# Technical data sheet

## Truss-head bolt with flange nut

Item no. 6406142

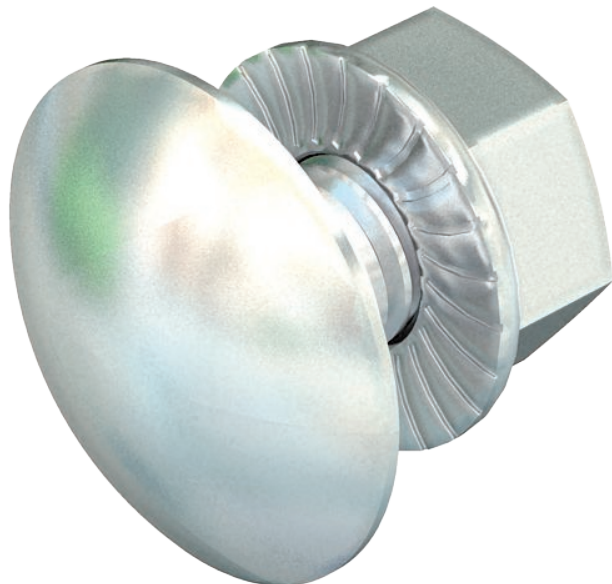

Truss-head bolt with square neck and combination nut.




VA Stainless steel, rustproof 1.4401

### Master data

|                          |                                      |
|--------------------------|--------------------------------------|
| Item no.                 | 6406142                              |
| Type                     | FRSB 6x12 A4                         |
| Description 1            | Truss-head bolt                      |
| Description 2            | with combination nut                 |
| Dimension                | M6x12                                |
| Material                 | Stainless steel, material no. 1.4401 |
| Material symbol          | A4                                   |
| Smallest sales unit (VG) | 100 Piece                            |
| Weight                   | 0,80 kg/100 pc.                      |

### Technical data

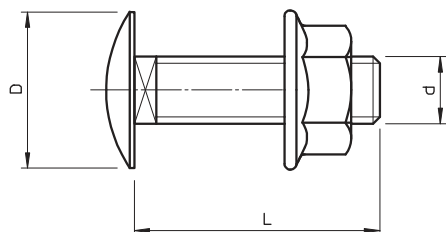

|                  |                                     |
|------------------|-------------------------------------|
| Length           | 12,00 mm                            |
| Dimension D      | 13,50 mm                            |
| Dimension d      | 6,00 mm                             |
| Dimension L      | 12,00 mm                            |
| WAF              | 10,00 mm                            |
| Dimension        | M 6 x 12 mm                         |
| Resistance grade | A4-50                               |
| Thread           | M6                                  |
| Thread metric    | 6                                   |
| With nut         | <input checked="" type="checkbox"/> |