

Technical data sheet

Adjustable bend, vertical, NS 60

Item no. 6213162



90° adjustable vertical bend, for cable ladders with light-duty rung (NS) and a side height of 60 mm.



St	Steel
FT	Hot-dip galvanised

Additional product text, instruction	The fitting is shipped in an unmounted state including adjustable connectors and the appropriate bolts.
Additional product text 2	Additional widths are available on request.

Master data

Item no.	6213162
Type	LGBV 650 NS FT
Description 1	Adjustable bend
Description 2	vertical, with NS rung
Dimension	60x500
Material	Steel
Material symbol	St
Surface	Hot-dip galvanised
Surface to DIN	DIN EN ISO 1461
Surface symbol	FT
Smallest sales unit (VG)	1,00 Piece
Weight	318,70 kg/100 pc.


Technical data sheet

Adjustable bend, vertical, NS 60

Item no. 6213162



Technical data

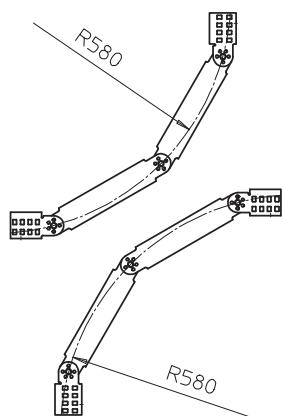

Width	500,00 mm
Side height	60,00 mm
Dimension R	580,00 mm
Bend (angle)	90°
Rung version	Profile unperforated
Side rail version	Flat profile
Suitable for maintaining electrical function	☐
Rail thickness	1,50 mm
Rustproof steel, pickled	☐
Hinged	☒
Side perforation	☐
Wide-span version	☐