

Technical data sheet

Chuck jaw, light-duty TKS

Item no. 6355835



Chuck jaw with hexagonal nut for direct fastening of structures to steel girders.

The clamping range of the chuck jaw is limited to the maximum fastening thickness of 36 mm.




VA Stainless steel, rustproof 1.4571

Master data

Item no.	6355835
Type	TKS-L36 M8 A4
Description 1	Tensioning claw, light
Dimension	M8x80
Material	Stainless steel, material no. 1.4571
Material symbol	A4
Smallest sales unit (VG)	1 Piece
Weight	16,00 kg/100 pc.

Technical data

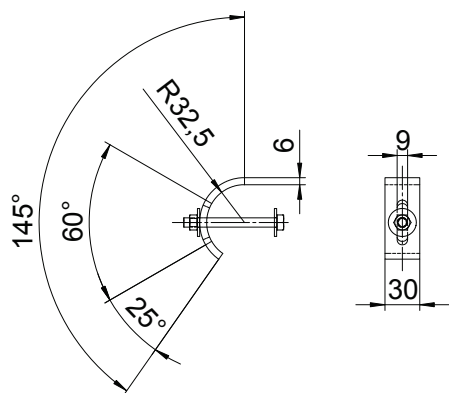

Height	36,00 mm
Thread size M	8
F in kN	10,00 kN
F in N	10.000,00 N
Bolt	M8 x 80