

# Technical data sheet

## Magic straight connector set A2

Item number: 6068966



Cable tray connector with quick fastening for the screwless connection of perforated cable trays with a side height of 60 mm. The optimised design means that the connector can be used to create radii and as a length compensation piece for large temperature deviations.



**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	6068966
Type	KTSMV 640 A2
Description 1	Straight connector set
Description 2	for cable tray Magic
Manufacturer	OBO
Dimension	60x400x200
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	50.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,3836 kg CO2e / 1 Piece


# Technical data sheet

## Magic straight connector set A2

Item number: 6068966



### Dimensions

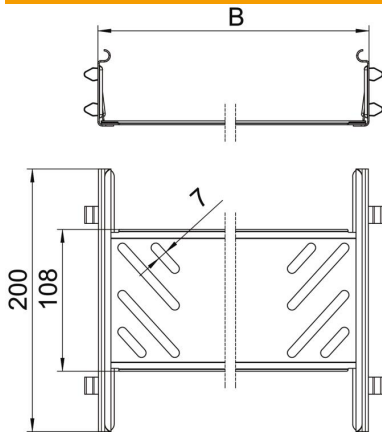

Dimension	60x400
Length	200 mm
Width	400 mm
Height	60 mm
Plate thickness	1 mm
Dimension B	400 mm

### Technical data

Version for	Straight connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	60 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screwless connector