

Technical data sheet

Vertical bend, three-compartment, height 58 mm

Item number: 7400667



Vertical bend, two-compartment, for vertical direction changes of screed-covered underfloor ducts (wall connections, supplies). Only compatible with the UZD250-4/350-4



St Steel

FS Strip galvanized

Master data

Item number	7400667
Type	KV3 35058-2
Description 1	Vertical bend
Description 2	3 compartments for EÜK-2
Manufacturer	OBO
Dimension	430x177,7x177,7
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	138.24 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,8106 kg CO2e / 1 Piece


Technical data sheet

Vertical bend, three-compartment, height 58 mm

Item number: 7400667



Dimensions

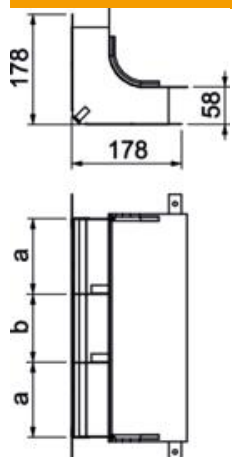

Length	178 mm
Width	350 mm
Height	58 mm
Dimension a	120 mm
Dimension b	110 mm
Dimension h	58 mm

Technical data

Number of fixed partitions	2
Number of compartments	3 St.
Suitable for screed-flush closed underfloor ducts	no
Suitable for screed-covered underfloor ducts	yes
Trunking width, min.	350 mm
Duct height, min.	58 mm
Cross-section, draw a	6341 mm ²
Cross-section, draw b	6112 mm ²