

Technical data sheet

Clamping angle KWH A2

Item number: 6355307



Clamping angle, with hammer-head bolt, type KWH, for fixing in the profile rail, type CPS 5.
Choose the clamping angle according to the thickness of the flange.
The clamping angle is used in conjunction with profile rails of slot width 22 mm (e.g. type CPS 5).



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6355307
Description 1	Clamping profile
Description 2	with hook screw, h = 5 mm
Manufacturer	OBO
Dimension	60x50
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	5
Unit of quantity	Pair
Weight	65 kg
Weight unit	kg/100 pairs


Technical data sheet

Clamping angle KWH A2

Item number: 6355307



Dimensions

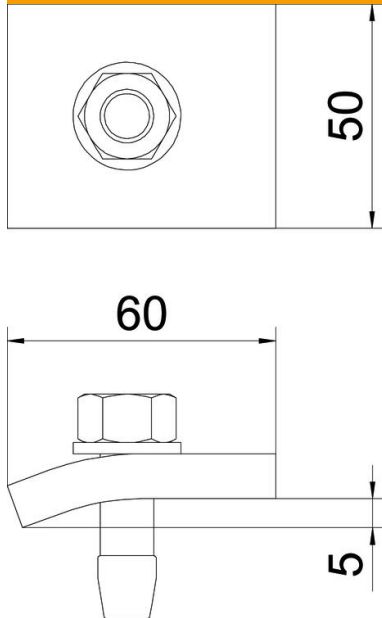

Height	5 mm
--------	------

Technical data

F in kN	5.7 kN
Suitable for flange thickness, max.	8 mm
Suitable for flange thickness, min.	3 mm
Thread metric	12
Bolt	M12 x 40