


Technical data sheet

Clamping angle KWS A2

Item number: 6355420

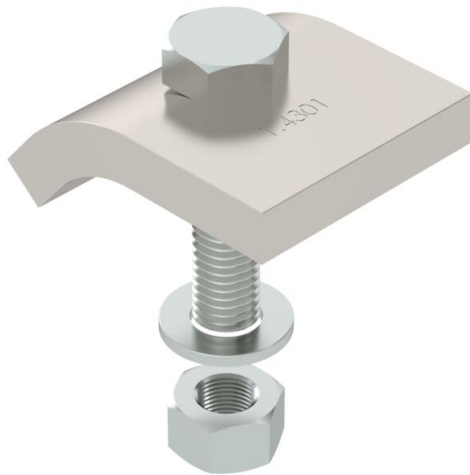

Clamping angle, with hexagonal bolt, type KWS, for direct fixing of constructions to steel girder flanges.
Choose the clamping angle according to the thickness of the flange.



A2 Stainless steel

2B Bright, treated

Master data

Item number	6355420
Description 1	Clamping profile
Description 2	with hexagon screw, h = 15 mm
Manufacturer	OBO
Dimension	60x50
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	5
Unit of quantity	Pair
Weight	63.2 kg
Weight unit	kg/100 pairs


Technical data sheet

Clamping angle KWS A2

Item number: 6355420



Dimensions

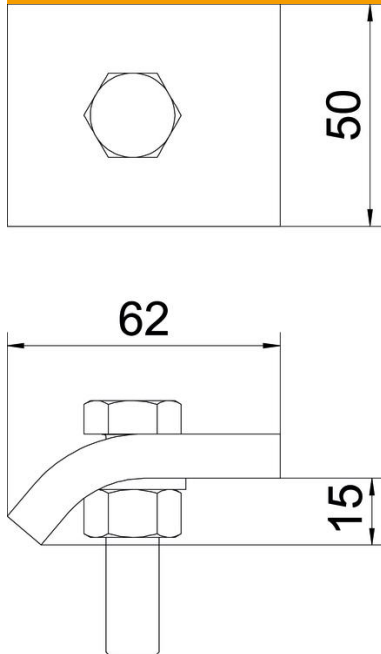

Height	15 mm
--------	-------

Technical data

F in kN	5.7 kN
Suitable for flange thickness, max.	18 mm
Suitable for flange thickness, min.	12 mm
Thread metric	12
Bolt	M12 x 50