

Technical data sheet

Clamping angle KWS A2

Item number: 6355447



Clamping angle, with hexagonal bolt, type KWS, for direct fixing of constructions to steel girder flanges.
Choose the clamping angle according to the thickness of the flange.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	6355447
Description 1	Clamping profile
Description 2	with hexagon screw, h = 25 mm
Manufacturer	OBO
Dimension	60x50
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	5
Unit of quantity	Pair
Weight	81 kg
Weight unit	kg/100 pairs


Technical data sheet

Clamping angle KWS A2


Item number: 6355447



Dimensions

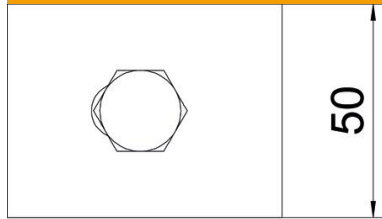

Height 25 mm

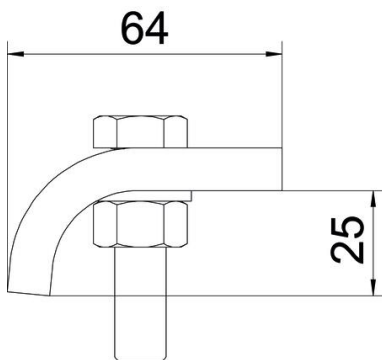

Technical data

F in kN	5.7 kN
Suitable for flange thickness, max.	28 mm
Suitable for flange thickness, min.	22 mm
Thread metric	12
Bolt	M12 x 60