

Technical data sheet

90° bend 110 FS

Item number: 6225122



90° bend, horizontal, with welded rung for all cable ladder types of 110 mm side height.
Connectors should be ordered separately and in the appropriate quantity.



St	Steel
FS	Strip galvanized

Master data

Item number	6225122
Type	LB 90 1120 R3 FS
Description 1	90° bend
Description 2	for cable ladder
Manufacturer	OBO
Dimension	110x200
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	355.3 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	9,0504 kg CO2e / 1 Piece


Technical data sheet

90° bend 110 FS

Item number: 6225122



Dimensions

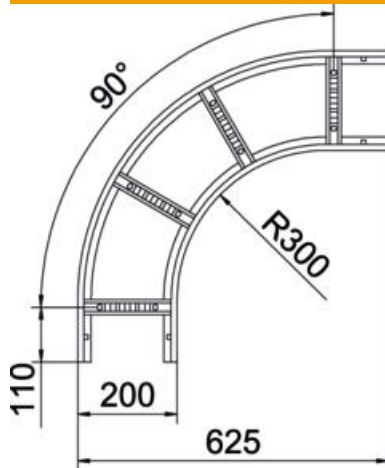

Width	200 mm
Height	110 mm
Dimension B	200 mm
Dimension R	200 mm

Technical data

Bend (angle)	90°
Version of the rungs	Profile perforated
Side rail version	Flat profile
Connector version	Without connectors
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm