

# Technical data sheet

90° bend 60 A2

Item number: 6225084



90° bend, horizontal, with welded rung for all cable ladder types of 60 mm side height.  
Connectors should be ordered separately and in the appropriate quantity.



**A2** Stainless steel

**2B** Bright, treated

## Master data

Item number	6225084
Type	LB 90 630 R3 A2
Description 1	90° bend
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x300
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	322.3 kg
Weight unit	kg/100 pc.


# Technical data sheet

90° bend 60 A2

Item number: 6225084



## Dimensions

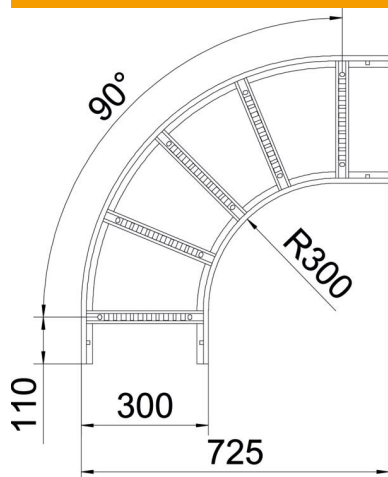

Width	300 mm
Height	60 mm
Dimension B	300 mm
Dimension R	300 mm

## Technical data

Bend (angle)	90°
Version of the rungs	Profile perforated
Side rail version	Flat profile
Connector version	Without connectors
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm