

Technical data sheet

Cover for articulated bend element FT

Item number: 6226244



Cover with sash locks for covering adjustable bends with welded rungs.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6226244
Type	LGBED 800 FT
Description 1	Cover for articulated bend
Description 2	vertical, with turn buckle
Manufacturer	OBO
Dimension	B800
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	196 kg
Weight unit	kg/100 pc.


Technical data sheet

Cover for articulated bend element FT

Item number: 6226244



Dimensions

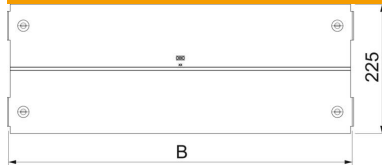

Width	800 mm
Plate thickness	1.25 mm
Dimension B	800 mm

Technical data

Bend (angle)	Adjustable
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	no
Change of direction	Vertical, rising/falling
Rustproof steel, pickled	no
Hinged	no