

Technical data sheet

Adjustable bend, vertical 110 FS

Item number: 6218822



90° adjustable vertical bend, for all cable ladder types with a side height of 110 mm.
The fitting is shipped in an unmounted state including adjustable connectors and the appropriate bolts.



St	Steel
FS	Strip galvanized

Master data

Item number	6218822
Type	LGBV 112 VS FS
Description 1	Adjustable bend
Description 2	vertical, with VS rung
Manufacturer	OBO
Dimension	110x200
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	402 kg
Weight unit	kg/100 pc.


Technical data sheet

Adjustable bend, vertical 110 FS

Item number: 6218822



Dimensions

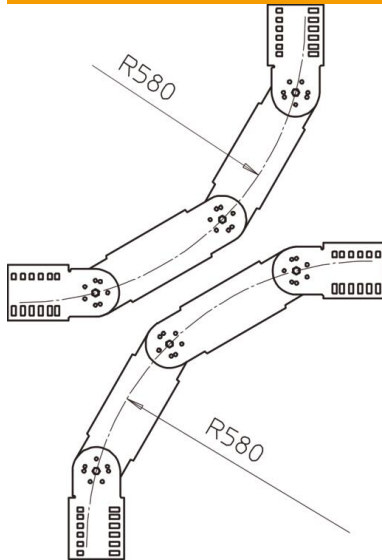

Width	200 mm
Height	110 mm

Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Hinged	yes
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm