

Technical data sheet

Adjustable bend, vertical, NS 60 FT

Item number: 6213138



90° adjustable vertical bend, for cable ladders with light-duty rung (NS) and a side height of 60 mm.
The fitting is shipped in an unmounted state including adjustable connectors and the appropriate bolts.
Additional widths are available on request.



St Steel

FT Hot-dip galvanised

Master data

Item number	6213138
Description 1	Adjustable bend
Description 2	vertical, with NS rung
Manufacturer	OBO
Dimension	60x200
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	249.9 kg
Weight unit	kg/100 pc.


Technical data sheet

Adjustable bend, vertical, NS 60 FT

Item number: 6213138



Dimensions

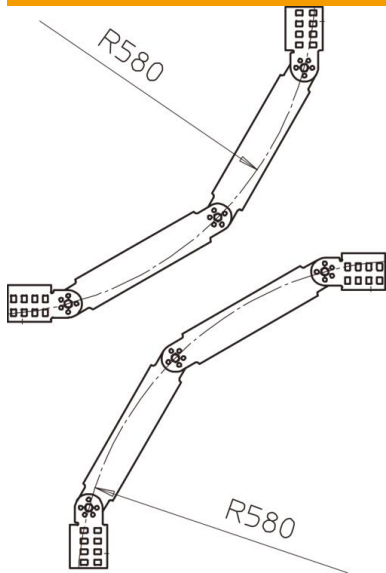

Width	200 mm
Height	60 mm

Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Hinged	yes
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm