


# Technical data sheet

Cable bracket, vertical, for PYROLINE® fire protection ducts, height 60 mm  
Item number: 7215292

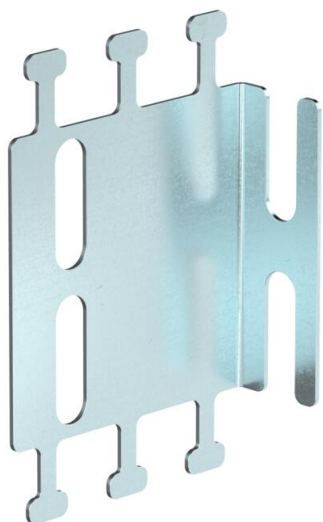

Universal cable bracket for the vertical installation of cables in PYROLINE® Con fire protection ducts made of fibreglass-reinforced, lightweight concrete, as well as PYROLINE® Rapid made of sheet steel with an internal coating. The holders are plugged over the head of the loosened fastening screw and then screwed tight to it. The cables can be fastened using cable ties on the lugs or in the slots of the holder. This safely supports the cable weight. Plan at least two cable brackets per metre during installation.

St	Steel
FS	Strip galvanized

## Master data

Item number	7215292
Type	LHS 60
Description 1	Cable fixing device vertical
Description 2	for fire protection duct
Manufacturer	OBO
Dimension	60x20
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	10
Unit of quantity	Piece
Weight	3.507 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1984 kg CO2e / 1 Piece

# Technical data sheet

Cable bracket, vertical, for PYROLINE® fire protection ducts, height 60 mm  
Item number: 7215292



**Dimensions**

Top view: 90 mm width, 61 mm height.  
Side view: 21 mm height, 60 mm width.  
Detail: 8 mm thickness.

Length	60 mm
Width	90 mm
Height	41 mm
Dimension B	21 mm
Dimension b	8 mm
Dimension H	61 mm
Dimension L	90 mm
Dimension I	60 mm

Technical data		
	Type of accessory	Miscellaneous