


Technical data sheet

Cover LK4 D 40

Item number: 6178484

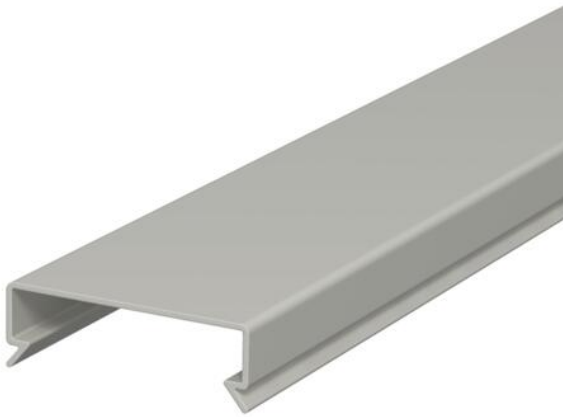

Trunking cover for replacement requirements.
Flushfloor design with predetermined break points



PVC Polyvinylchloride

Master data

Item number	6178484
Type	LK4 D 40
Description 1	Cover
Description 2	for LK4 / LK4/N
Manufacturer	OBO
Dimension	40mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	13.5 kg
Weight unit	kg/100 m

Dimensions



Length	2,000 mm
Width	40 mm
Dimension a	46.2 mm

Technical data sheet

Cover LK4 D 40

Item number: 6178484



Technical data

for duct width	40 mm
Halogen-free	no
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C