


Technical data sheet

Cover LK4 D 80

Item number: 6178488

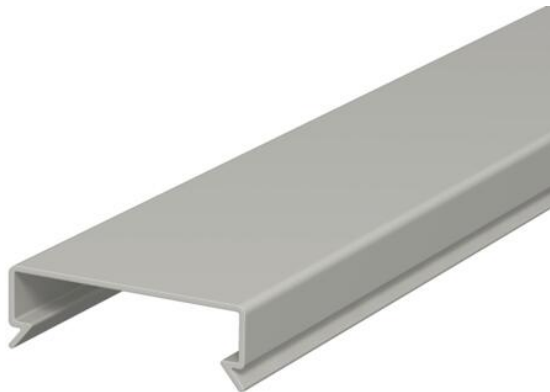

Trunking cover for replacement requirements.
Flushfloor design with predetermined break points



PVC Polyvinylchloride

Master data

Item number	6178488
Type	LK4 D 80
Description 1	Cover
Description 2	for LK4 / LK4/N
Manufacturer	OBO
Dimension	80mm
Colour	Stone grey; RAL 7030
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	27 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,6145 kg CO2e / 1 Meter

Dimensions



Length	2,000 mm
Width	80 mm
Dimension a	87 mm

Technical data sheet

Cover LK4 D 80

Item number: 6178488



Technical data

for duct width	80 mm
Halogen-free	no
Self-extinguishing	yes
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C