

# Technical data sheet


## Cable duct, type LKM 40040

Item number: 6246990



Duct cover and base with base perforation.

Equipotential bonding is guaranteed between the cover and the base without any additional aids.

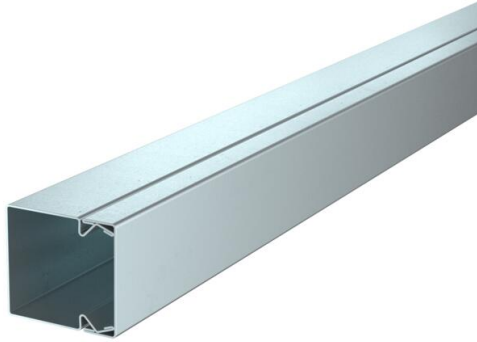

- St** Steel
- FS** Strip galvanized

### Master data


Item number	6246990
Type	LKM40040FS
Description 1	Cable trunking
Description 2	with base perforation
Manufacturer	OBO
Dimension	40x40x2000
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	117 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,2144 kg CO2e / 1 Meter

# Technical data sheet

## Cable duct, type LKM 40040

Item number: 6246990

### Dimensions

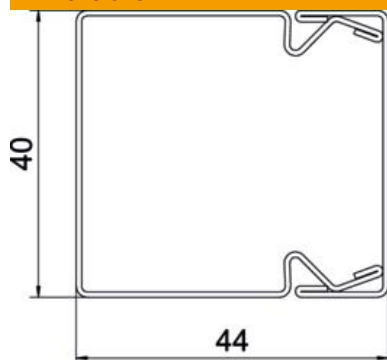

Length	2,000 mm
Width	40 mm
Height	44 mm

### Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm <sup>2</sup> Ø 10.5 mm (without socket)	6
Number of cables NYM 3 x 2.5 mm <sup>2</sup> Ø 11.5 mm (without socket)	6
Number of cables NYM 5 x 1.5 mm <sup>2</sup> Ø 12.0 mm (without socket)	6
Number of insertable partitions	0
Version, cable trunking cover	Loose
Fastening type	Base perforation
Base perforation	with base perforation
Maintain electrical functions	no
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Delivery on a roll	no
Usable cross-section	1537 mm <sup>2</sup>
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Transparent	no