

# Technical data sheet

## Cable duct, type LKM 40060

Item number: 6248519



Duct cover and base with base perforation.  
Equipotential bonding is guaranteed between the cover and the base without any additional aids.



- St** Steel
- FSK** Strip galvanized / plastic coated

### Master data

Item number	6248519
Type	LKM40060RW
Description 1	Cable trunking
Description 2	with base perforation
Manufacturer	OBO
Dimension	40x60x2000
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	157.3 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,292 kg CO2e / 1 Meter


# Technical data sheet

## Cable duct, type LKM 40060



Item number: 6248519

### Dimensions

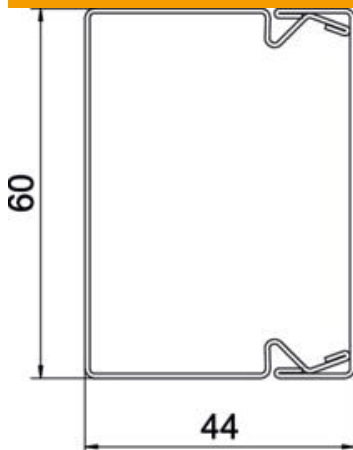

Length	2,000 mm
Width	60 mm
Height	44 mm

### Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm <sup>2</sup> Ø 10.5 mm (without socket)	10
Number of cables NYM 3 x 2.5 mm <sup>2</sup> Ø 11.5 mm (without socket)	10
Number of cables NYM 5 x 1.5 mm <sup>2</sup> Ø 12.0 mm (without socket)	8
Number of insertable partitions	0
Version, cable trunking cover	Loose
Fastening type	Base perforation
Base perforation	with base perforation
Maintain electrical functions	no
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Delivery on a roll	no
Usable cross-section	2380 mm <sup>2</sup>
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Transparent	no