

Technical data sheet

Cable trunking, type LKM 60060

Item number: 6247091



Trunking cover and base with base perforation.
Equipotential bonding is guaranteed between the cover and the base without any additional aids. Note: LKM 60060 has no loop perforation in the base, a partition cannot be installed.



- St** Steel
- FS** Strip galvanized

Master data

Item number	6247091
Type	LKM60060FS
Description 1	Cable trunking
Description 2	with base perforation
Manufacturer	OBO
Dimension	60x60x2000
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	174.7 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	0,26 kg CO2e / 1 Meter


Technical data sheet

Cable trunking, type LKM 60060

Item number: 6247091



Dimensions

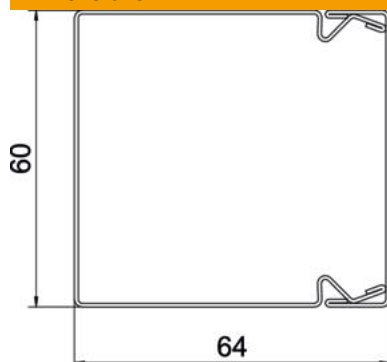

Length	2,000 mm
Width	60 mm
Height	64 mm

Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm ² Ø 10.5 mm (without socket)	20
Number of cables NYM 3 x 2.5 mm ² Ø 11.5 mm (without socket)	20
Number of cables NYM 5 x 1.5 mm ² Ø 12.0 mm (without socket)	16
Number of insertable partitions	0
Version, cable trunking cover	Loose
Fastening type	Base perforation
Base perforation	with base perforation
Maintain electrical functions	no
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Delivery on a roll	no
Usable cross-section	3551 mm ²
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Transparent	no