

Technical data sheet

Cable trunking, type LKM 60060

Item number: 6248608



Trunking cover and base with base perforation.
Equipotential bonding is guaranteed between the cover and the base without any additional aids. Note: LKM 60060 has no loop perforation in the base, a partition cannot be installed.



- St** Steel
- FSK** Strip galvanized / plastic coated

Master data

| | |
|------------------------------------|-----------------------------------|
| Item number | 6248608 |
| Type | LKM60060RW |
| Description 1 | Cable trunking |
| Description 2 | with base perforation |
| Manufacturer | OBO |
| Dimension | 60x60x2000 |
| Colour | Pure white; RAL 9010 |
| Material | Steel |
| Surface | Strip galvanized / plastic coated |
| Surface standard | DIN EN 10346 |
| Smallest sales unit | 2 |
| Unit of quantity | Metre |
| Weight | 174.7 kg |
| Weight unit | kg/100 m |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,2793 kg CO2e / 1 Meter |


Technical data sheet

Cable trunking, type LKM 60060

Item number: 6248608



Dimensions

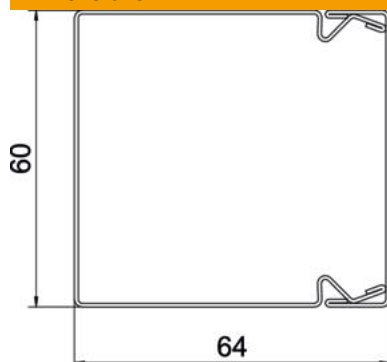

| | |
|--------|----------|
| Length | 2,000 mm |
| Width | 60 mm |
| Height | 64 mm |

Technical data

| | |
|---|-----------------------|
| Number of fixed partitions | 0 |
| Number of cables NYM 3 x 1.5 mm ² Ø 10.5 mm (without socket) | 20 |
| Number of cables NYM 3 x 2.5 mm ² Ø 11.5 mm (without socket) | 20 |
| Number of cables NYM 5 x 1.5 mm ² Ø 12.0 mm (without socket) | 16 |
| Number of insertable partitions | 0 |
| Version, cable trunking cover | Loose |
| Fastening type | Base perforation |
| Base perforation | with base perforation |
| Maintain electrical functions | no |
| Halogen-free | yes |
| Cable retaining clip | no |
| Duct connector | no |
| Delivery on a roll | no |
| Usable cross-section | 3551 mm ² |
| Protection rating | IP30 |
| Protective film | no |
| Protection rating IK code | IK10 |
| Permitted temperature range, max. | 90 °C |
| Permitted temperature range, min. | -5 °C |
| Transparent | no |