

Technical data sheet

Cable trunking, type LKM 60150

Item number: 6248640



Trunking cover and base with base perforation.

Equipotential bonding is guaranteed between the cover and the base without any additional aids.

The base contains loop perforation allowing the attachment of the partition.



St	Steel
FSK	Strip galvanized / plastic coated

Master data

Item number	6248640
Type	LKM60150RW
Description 1	Cable trunking
Description 2	with base perforation
Manufacturer	OBO
Dimension	60x150x2000
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	280.1 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	4,1863 kg CO2e / 1 Meter


Technical data sheet

Cable trunking, type LKM 60150

Item number: 6248640



Dimensions

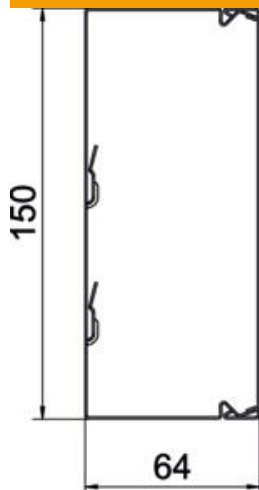

Length	2,000 mm
Width	150 mm
Height	64 mm

Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm ² Ø 10.5 mm (without socket)	56
Number of cables NYM 3 x 2.5 mm ² Ø 11.5 mm (without socket)	48
Number of cables NYM 5 x 1.5 mm ² Ø 12.0 mm (without socket)	48
Number of insertable partitions	2
Version, cable trunking cover	Loose
Fastening type	Base perforation
Base perforation	with base perforation
Maintain electrical functions	no
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Delivery on a roll	no
Usable cross-section	9148 mm ²
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Transparent	no