

# Technical data sheet

End piece, for cable trunking type LKM 80080

Item number: 6248454



End piece for closing the LKM ducts.



**St** Steel

**FSK** Strip galvanized / plastic coated

## Master data

Item number	6248454
Type	LKM E80080RW
Description 1	End piece
Manufacturer	OBO
Dimension	80x80mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,3078 kg CO2e / 1 Piece


# Technical data sheet

End piece, for cable trunking type LKM 80080

Item number: 6248454



## Dimensions

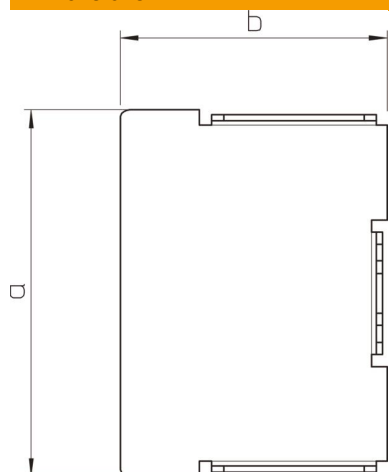

Length	21 mm
Width	80 mm
Height	80 mm
Dimension a	80 mm
Dimension b	80 mm

## Technical data

Version for	Left/right
Fastening type	Lockable
Maintain electrical functions	no
Halogen-free	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C