

Technical data sheet

Flat angle, for cable trunking type LKM 40040

Item number: 6248993



Flat angle including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover



St Steel

FSK Strip galvanized / plastic coated

Master data

Item number	6248993
Type	LKM F40040RW
Description 1	Flat angle
Description 2	with cover
Manufacturer	OBO
Dimension	40x40mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	37.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,6915 kg CO2e / 1 Piece


Technical data sheet

Flat angle, for cable trunking type LKM 40040

Item number: 6248993



Dimensions

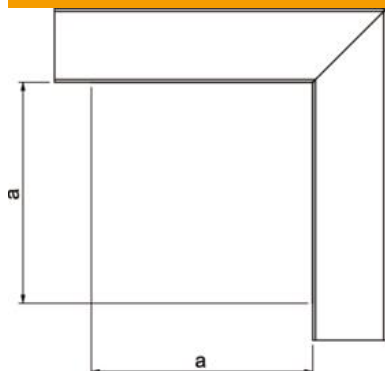

Length	180 mm
Width	40 mm
Height	44 mm
Dimension a	140 mm

Technical data

Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions for duct dimension	no 40 x 40
Halogen-free	yes
Duct height, min.	44 mm
Trunking depth	44 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm