

Technical data sheet

Flat angle, for cable trunking type LKM 40060

Item number: 6249000



Flat angle including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover



St	Steel
FSK	Strip galvanized / plastic coated

Master data

Item number	6249000
Type	LKM F40060RW
Description 1	Flat angle
Description 2	with cover
Manufacturer	OBO
Dimension	40x60mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	47.4 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle, for cable trunking type LKM 40060

Item number: 6249000



Dimensions

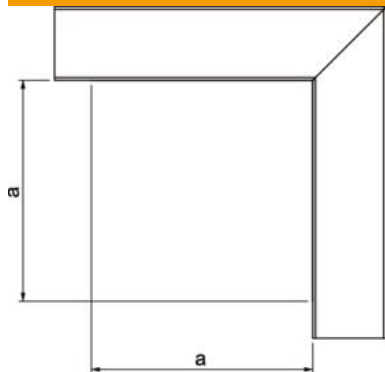

Length	200 mm
Width	60 mm
Height	44 mm
Dimension a	140 mm

Technical data

Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	40 x 60
Halogen-free	yes
Duct height, min.	44 mm
Trunking depth	44 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm