

# Technical data sheet

Flat angle, for cable duct type LKM 60100

Item number: 6249507



Flat angle including cover for changing the direction of the LKM ducts.  
Equipotential bonding without additional aids, between base and cover



**St** Steel

**FSK** Strip galvanized / plastic coated

## Master data

Item number	6249507
Type	LKM F60100RW
Description 1	Flat angle
Description 2	with cover
Manufacturer	OBO
Dimension	60x100mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	63.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,3677 kg CO2e / 1 Piece


# Technical data sheet

Flat angle, for cable duct type LKM 60100

Item number: 6249507



## Dimensions

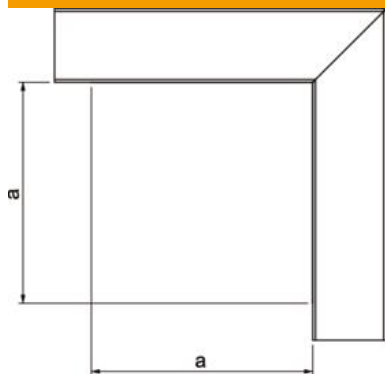

Length	240 mm
Width	100 mm
Height	64 mm
Dimension a	140 mm

## Technical data

Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	yes
for duct dimension	60 x 100
Halogen-free	yes
Duct height, min.	64 mm
Trunking depth	64 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm