

Technical data sheet

Flat angle, for cable trunking type LKM 60150

Item number: 6248012



Flat angle including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover



St	Steel
FS	Strip galvanized

Master data

Item number	6248012
Type	LKM F60150FS
Description 1	Flat angle
Description 2	with cover
Manufacturer	OBO
Dimension	60x150mm
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	113.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	5,0755 kg CO2e / 1 Piece


Technical data sheet

Flat angle, for cable trunking type LKM 60150

Item number: 6248012



Dimensions

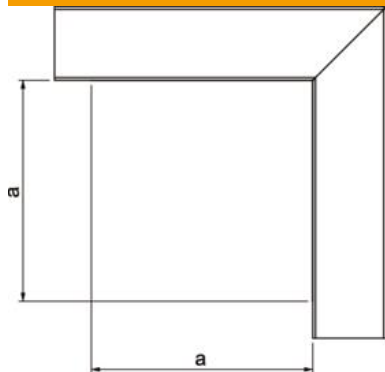

Length	290 mm
Width	150 mm
Height	64 mm
Dimension a	140 mm

Technical data

Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	60 x 150
Halogen-free	yes
Duct height, min.	64 mm
Trunking depth	64 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm