

Technical data sheet

Flat angle, for cable trunking type LKM 80080

Item number: 6248428



Flat angle including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover



St Steel

FSK Strip galvanized / plastic coated

Master data

Item number	6248428
Type	LKM F80080RW
Description 1	Flat angle
Description 2	with cover
Manufacturer	OBO
Dimension	80x80mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	80 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	3,4772 kg CO2e / 1 Piece

Technical data sheet


Flat angle, for cable trunking type LKM 80080

Item number: 6248428



Dimensions

Length	240 mm
Width	80 mm
Height	80 mm
Dimension a	160 mm

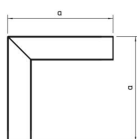

Technical data

Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	80 x 80
Halogen-free	yes
Duct height, min.	80 mm
Trunking depth	80 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm