

Technical data sheet

Internal corner, for cable trunking type LKM 60150

Item number: 6249647



Internal corner for changing the direction of the LKM trunking.
Equipotential bonding without additional aids, between base and cover



St	Steel
FSK	Strip galvanized / plastic coated

Master data

Item number	6249647
Type	LKM I60150RW
Description 1	Internal corner
Manufacturer	OBO
Dimension	60x150mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	48.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,1279 kg CO2e / 1 Piece

Technical data sheet


Internal corner, for cable trunking type LKM 60150

Item number: 6249647



Dimensions

Length	160 mm
Width	150 mm
Height	64 mm
Dimension a	160 mm

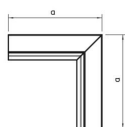

Technical data

Version for	Base
Fastening type	Base perforation
Maintain electrical functions	no
Halogen-free	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm