

Technical data sheet

Trunking clamp, LKM, trunking width 150 and 200 mm

Item number: 6249888



The duct clamp keeps the inserted cables in the trunking, thus simplifying installation on walls and ceilings. The duct clamps are plugged onto the loop perforation and locked on the side wall. Suitable for trunking width 150 mm and 200 mm.



St	Steel
GBP	galvanised, blue passivated

Master data

Item number	6249888
Type	LKM K140
Description 1	Trunking clamp
Manufacturer	OBO
Dimension	140mm
Colour	zinc
Material	Steel
Surface	galvanised, blue passivated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	3.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0786 kg CO2e / 1 Piece


Technical data sheet

Trunking clamp, LKM, trunking width 150 and 200 mm

Item number: 6249888



Dimensions

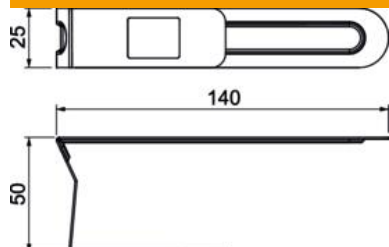

Length	25 mm
Width	141 mm
Height	49 mm
Dimension a	25 mm
Dimension b	141 mm
Dimension c	49 mm

Technical data

Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 150 - 60 x 200
Halogen-free	yes
With equipotential bonding	no
Cover width	150 mm
Cover width 2	200 mm
Protection rating	IP30
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C