


Technical data sheet

Trunking clamp, LKM, trunking width 100 mm

Item number: 6249884

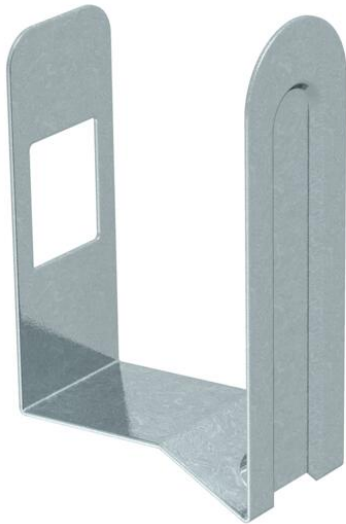

The duct clamp keeps the inserted cables in the duct, thus simplifying installation on walls and ceilings. The duct clamps are plugged onto the loop perforation and locked on the side wall. Suitable for duct width 100 mm.



St	Steel
GBP	galvanised, blue passivated

Master data

Item number	6249884
Type	LKM K80
Description 1	Trunking clamp
Manufacturer	OBO
Dimension	80mm
Colour	zinc
Material	Steel
Surface	galvanised, blue passivated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	2.7 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,059 kg CO2e / 1 Piece


Technical data sheet

Trunking clamp, LKM, trunking width 100 mm

Item number: 6249884



Dimensions

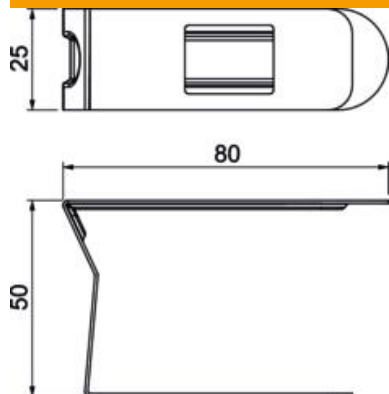

Length	25 mm
Width	81 mm
Height	49 mm
Dimension a	25 mm
Dimension b	81 mm
Dimension c	49 mm

Technical data

Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	60 x 100
Halogen-free	yes
With equipotential bonding	no
Cover width	100 mm
Protection rating	IP30
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C