


Technical data sheet

T piece, for cable trunking type LKM 40060

Item number: 6249264



T piece including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover

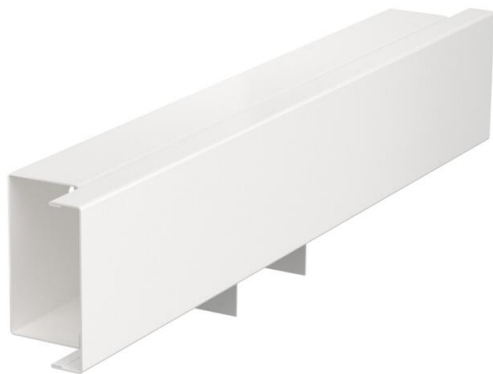

St

Steel

FSK

Strip galvanized / plastic coated

Master data

Item number	6249264
Type	LKM T40060RW
Description 1	T piece
Description 2	with cover
Manufacturer	OBO
Dimension	40x60mm
Colour	Pure white; RAL 9010
Material	Steel
Surface	Strip galvanized / plastic coated
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	46.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,6832 kg CO2e / 1 Piece

Technical data sheet

T piece, for cable trunking type LKM 40060

Item number: 6249264



Dimensions

Length	300 mm
Width	60 mm
Height	44 mm
Dimension a	300 mm



Technical data

Departing width	60 mm
Departing height	44 mm
Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	40 x 60
Halogen-free	yes
Duct height, min.	44 mm
Trunking depth	44 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C